


# Technical data sheet

T piece, for cable trunking type LKM 60060

Item number: 6249671



T piece including cover for changing the direction of the LKM trunking.  
Equipotential bonding without additional aids, between base and cover

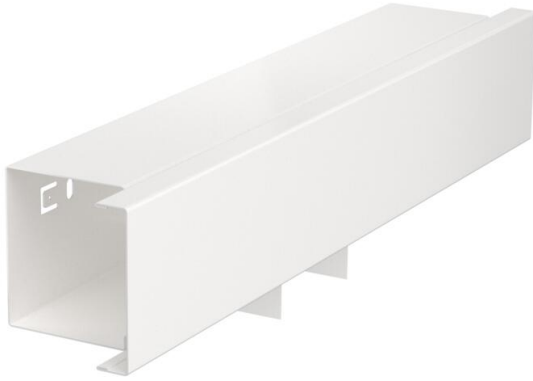

**St** Steel

**FSK** Strip galvanized / plastic coated

## Master data

Item number	6249671
Type	LKM T60060RW
Description 1	T piece
Description 2	with cover
Manufacturer	OBO
Dimension	60x60mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	54.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,9462 kg CO2e / 1 Piece

# Technical data sheet

T piece, for cable trunking type LKM 60060

Item number: 6249671



## Dimensions

Length	300 mm
Width	60 mm
Height	64 mm
Dimension a	300 mm



## Technical data

Departing width	60 mm
Departing height	64 mm
Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	60 x 60
Halogen-free	yes
Duct height, min.	64 mm
Trunking depth	64 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C