


Technical data sheet

T piece for cable duct type LKM 60100

Item number: 6249701



T piece including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover

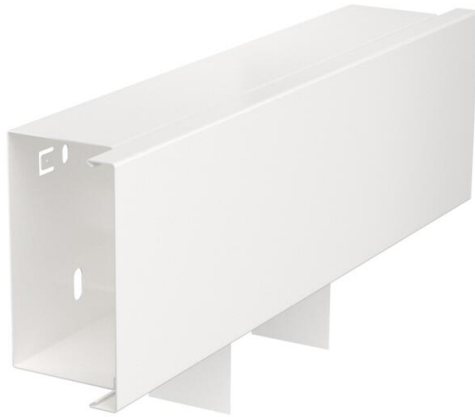

St Steel

FSK Strip galvanized / plastic coated

Master data

Item number	6249701
Type	LKM T60100RW
Description 1	T piece
Description 2	with cover
Manufacturer	OBO
Dimension	60x100mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	69.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,625 kg CO2e / 1 Piece

Technical data sheet


T piece for cable duct type LKM 60100

Item number: 6249701



Dimensions

Length	300 mm
Width	100 mm
Height	64 mm
Dimension a	300 mm

 

Technical data

Departing width	100 mm
Departing height	64 mm
Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	yes
for duct dimension	60 x 100
Halogen-free	yes
Duct height, min.	64 mm
Trunking depth	64 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C