


Technical data sheet

T piece, for cable trunking type LKM 80080

Item number: 6248450



T piece including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover

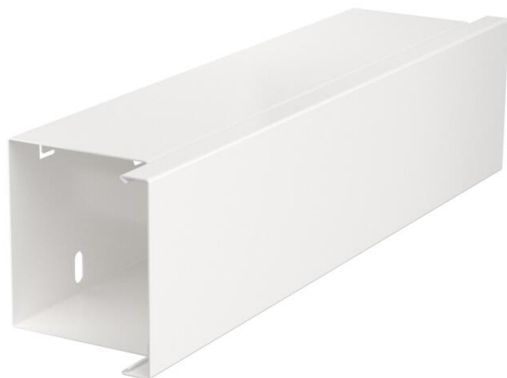

St

Steel

FSK

Strip galvanized / plastic coated

Master data

Item number	6248450
Type	LKM T80080RW
Description 1	T piece
Description 2	with cover
Manufacturer	OBO
Dimension	80x80mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	67.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,3887 kg CO2e / 1 Piece

Technical data sheet

T piece, for cable trunking type LKM 80080

Item number: 6248450



Dimensions

Length	300 mm
Width	80 mm
Height	80 mm
Dimension a	300 mm



Technical data

Departing width	80 mm
Departing height	80 mm
Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	80 x 80
Halogen-free	yes
Duct height, min.	80 mm
Trunking depth	80 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C