

# Technical data sheet

## Wiring trunking, type LKV 50050

Item number: 6178314



Wiring duct according to DIN EN 50085-2-3, incl. cover and base perforation, for horizontal and vertical routing of electrical cables in the switchgear cabinet. Designed as a DIN duct. Retainers are broken out without tools. The flush-floor routing of cables is possible through predetermined break points. Tested to DIN EN 50085-2-3. Special lengths on request.



**PVC** Polyvinylchloride

### Master data

Item number	6178314
Type	LKV 50050
Description 1	Slotted cable trunking system
Manufacturer	OBO
Dimension	50x50x2000
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	36
Unit of quantity	Metre
Weight	50 kg
Weight unit	kg/100 m


# Technical data sheet

## Wiring trunking, type LKV 50050

Item number: 6178314



### Dimensions

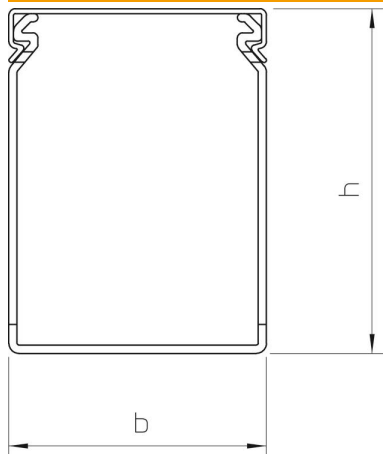

Length	2,000 mm
Width	50 mm
Height	50 mm

### Technical data

Side wall version	Slotted
Fastening type	Base perforation
Flexible	no
Halogen-free	no
With cover	yes
Usable cross-section	20.05 cm <sup>2</sup>
Slot spacing	12.5 mm
Slot width	5 mm
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C