


Technical data sheet

Luminaire support channel 50 FS

Item number: 6075000



Perforated luminaire support channel for cable routing and luminaire mounting.
Magnetic shield insulation without cover 20 dB, with cover 50 dB.

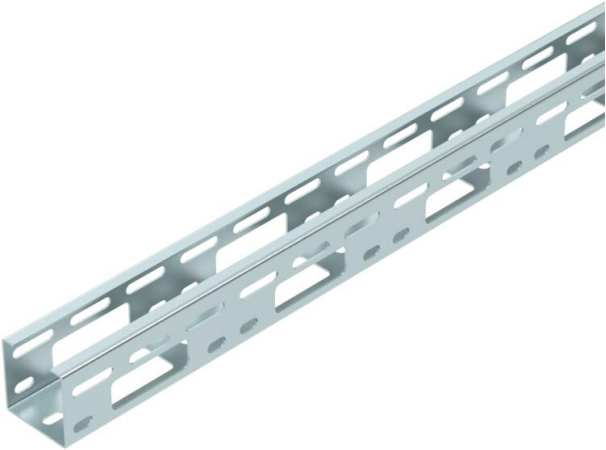

- St

Steel
- FS

Strip galvanized

Master data	
Item number	6075000
Description 1	Luminaire support rail
Manufacturer	OBO
Dimension	50x50x6000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	6
Unit of quantity	Metre
Weight	135.7 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	4,0438 kg COe / 1 Meter


Technical data sheet

Luminaire support channel 50 FS

Item number: 6075000



Dimensions

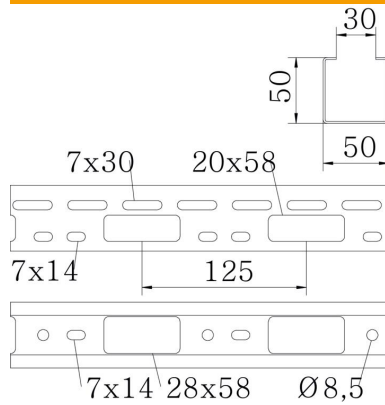

Length	6,000 mm
Width	50 mm
Height	50 mm
Plate thickness	1.5 mm
Dimension B	50 mm

Technical data

Connector version	Without connectors
Usable cross-section	22 cm ²

Loads

Support spacing 1.0 m	2.5 kN/m
Support spacing 1.5 m	2 kN/m
Support spacing 2.0 m	1.2 kN/m
Support spacing 2.5 m	0.85 kN/m
Support spacing 3.0 m	0.5 kN/m