


Technical data sheet

Luminaire support channel 50 FT

Item number: 6075005



Perforated luminaire support channel for cable routing and luminaire mounting.
Magnetic shield insulation without cover 20 dB, with cover 50 dB.

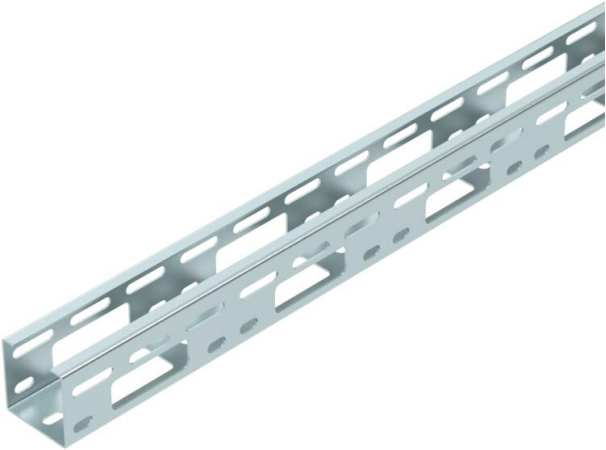

- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	6075005	
Type	LTS 50 FT	
Description 1	Luminaire support rail	
Manufacturer	OBO	
Dimension	50x50x6000	
Colour	zinc	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	6	
Unit of quantity	Metre	
Weight	144.666 kg	
Weight unit	kg/100 m	


Technical data sheet

Luminaire support channel 50 FT

Item number: 6075005



Dimensions

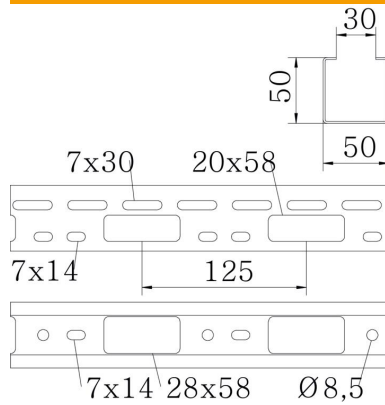

Length	6,000 mm
Width	50 mm
Height	50 mm
Plate thickness	1.5 mm
Dimension B	50 mm

Technical data

Connector version	Without connectors
Usable cross-section	22 cm ²

Loads

Support spacing 1.0 m	2.5 kN/m
Support spacing 1.5 m	2 kN/m
Support spacing 2.0 m	1.2 kN/m
Support spacing 2.5 m	0.85 kN/m
Support spacing 3.0 m	0.5 kN/m