


Technical data sheet

T piece 110 FT

Item number: 6225312



T piece, horizontal, with welded rung for all cable ladder types of 110 mm side height.
Connectors should be ordered separately and in the appropriate quantity.

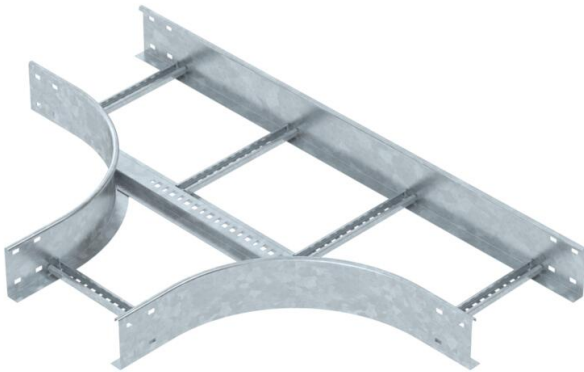

- St** Steel
- FT** Hot-dip galvanised

Master data

Item number	6225312
Type	LT 1130 R3 FT
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	110x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	781.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	17,1342 kg CO2e / 1 Piece


Technical data sheet

T piece 110 FT

Item number: 6225312



Dimensions

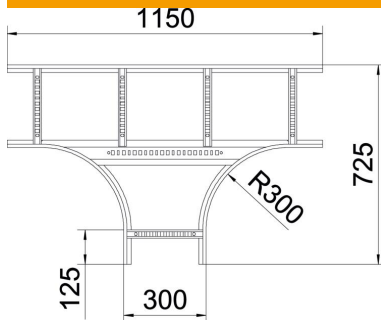

Width	300 mm
Height	110 mm
Dimension B	300 mm
Dimension R	300 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Connector version	Without connectors
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm