


Technical data sheet

T piece 110 FT

Item number: 6219407



T piece to create a horizontal branch, fittings for cable ladders of side height 110 mm. With connector perforation. Can be used indoors and outdoors. Connector and fastening material must be ordered separately. Fittings must be supported by the support structure.

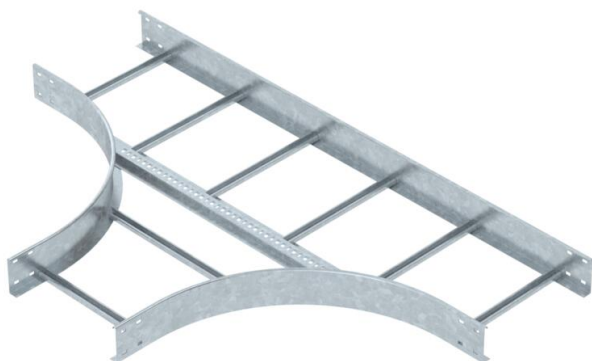

St Steel

FT Hot-dip galvanised

Master data

Item number	6219407
Type	LT 1140 R5 FT
Description 1	T piece
Description 2	for cable ladder, horizontal
Manufacturer	OBO
Dimension	110x400
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	1014 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	28,7872 kg CO2e / 1 Piece


Technical data sheet

T piece 110 FT

Item number: 6219407



Dimensions

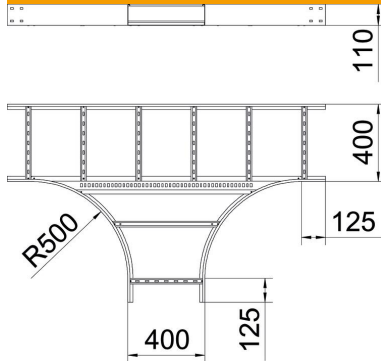

Width	400 mm
Height	110 mm
Dimension B	400 mm
Dimension R	500 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no