

# Technical data sheet

T piece 60 A4

Item number: 6225272



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.  
Connectors should be ordered separately and in the appropriate quantity.



**A4** Stainless steel

**2B** Bright, treated

## Master data

Item number	6225272
Type	LT 630 R3 A4
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x300
Colour	stainless steel
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	544.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	30,3854 kg CO2e / 1 Piece


# Technical data sheet

T piece 60 A4

Item number: 6225272



## Dimensions

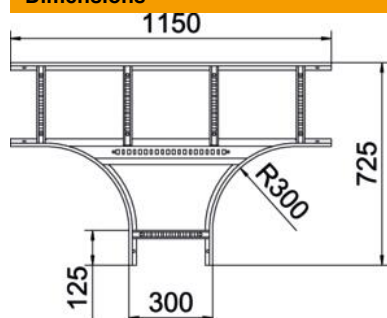

Width	300 mm
Height	60 mm
Dimension B	300 mm
Dimension R	300 mm

## Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Connector version	Without connectors
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm