


# Technical data sheet

## T piece VS 60 A2

Item number: 7162057



Tee, horizontal, for cable ladders with medium-duty rungs (VS) and a side height of 60 mm.  
Connectors should be ordered separately and in the appropriate quantity.

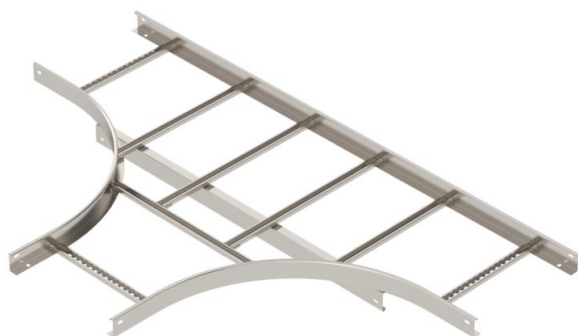

**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	7162057
Type	LT 640 VS A2
Description 1	T piece
Description 2	for cable ladder with VS rung
Manufacturer	OBO
Dimension	60x400
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	879 kg
Weight unit	kg/100 pc.


# Technical data sheet

## T piece VS 60 A2

Item number: 7162057



### Dimensions

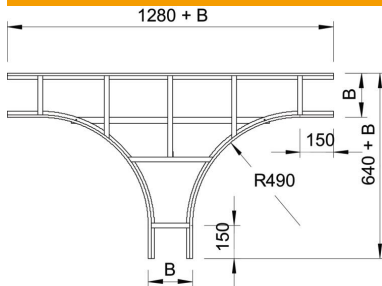

Width	400 mm
Height	60 mm
Dimension R	490 mm

### Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm