

Technical data sheet

T piece VS 60 A2

Item number: 7162081



Tee, horizontal, for cable ladders with medium-duty rungs (VS) and a side height of 60 mm.
Connectors should be ordered separately and in the appropriate quantity.



A2 Stainless steel

2B Bright, treated

Master data

Item number	7162081
Type	LT 660 VS A2
Description 1	T piece
Description 2	for cable ladder with VS rung
Manufacturer	OBO
Dimension	60x600
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	1104 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece VS 60 A2

Item number: 7162081



Dimensions

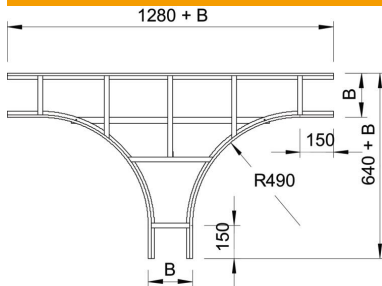

Width	600 mm
Height	60 mm
Dimension R	490 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm