


Technical data sheet

Straight connector 110 A2

Item number: 6216550

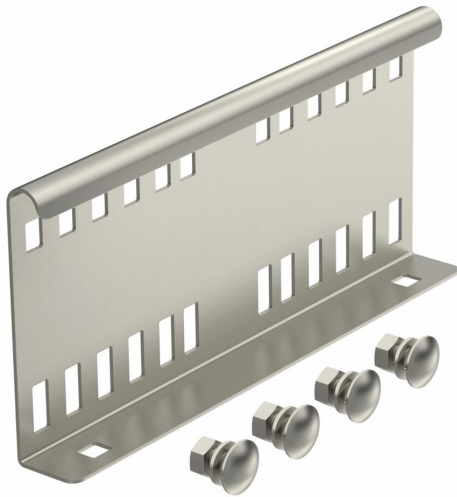

Straight connector as external connector to connect cable ladders and fittings with a side height of 110 mm.
The bolt fastening ensures the continuity of the equipotential bonding.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6216550
Type	LVG 110 A2
Description 1	Straight connector
Description 2	for cable ladder
Manufacturer	OBO
Dimension	114x250
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	50.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,9739 kg CO2e / 1 Piece


Technical data sheet

Straight connector 110 A2

Item number: 6216550



Dimensions

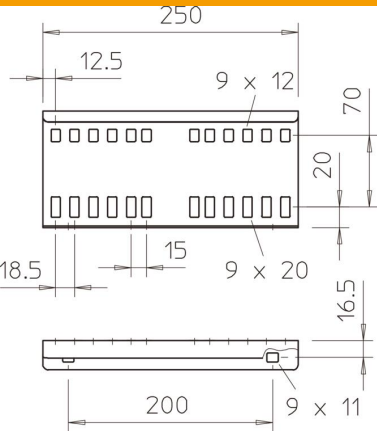

Dimension	114x250
Length	250 mm
Width	28 mm
Height	110 mm
Plate thickness	1.5 mm

Technical data

Version for	Straight connector
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	no
Suitable for cable tray system height	110 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screw connector