

Technical data sheet

Multi-Quick clip

Item number: 2153157



Flush-mounted clip to accept metric and PG pipes and Quick-Pipe® electrical installation pipes. Flexible clamping range of several millimetres. Universal fastening options on walls and ceilings and usable in a profile rail, both in indoor and protected outdoor areas. Toolless pipe mounting. Can also be arranged with OBO Quick clip or proQuick clip.



PA Polyamide

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 2153157 |
| Type | M-Quick 31-37LGR |
| Description 1 | Multi-Quick clip |
| Manufacturer | OBO |
| Dimension | 31-37mm |
| Colour | Light grey; RAL 7035 |
| Material | Polyamide |
| Smallest sales unit | 25 |
| Unit of quantity | Piece |
| Weight | 1.78 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0814 kg CO2e / 1 Piece |


Technical data sheet

Multi-Quick clip

Item number: 2153157



Dimensions

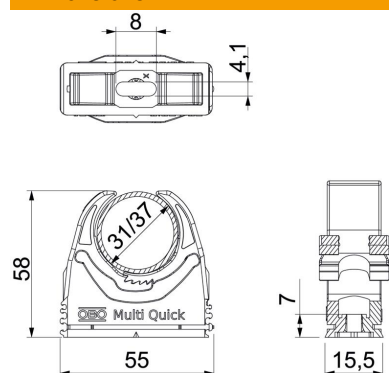

| | |
|-------------|---------|
| Dimension A | 55 mm |
| Dimension B | 15.5 mm |
| Dimension E | 8 mm |
| Dimension F | 4.1 mm |
| Dimension h | 7 mm |
| Dimension H | 58 mm |

Technical data

| | |
|-------------------------|---|
| Expandable | yes |
| Number of cables/pipes | 1 |
| Pull-out value | 65 N |
| Fastening type | Screw hole |
| Flame-resistant | acc. to VDE 0471/DIN 695 Part 2-1, test temperature 650°C |
| Closed | no |
| Halogen-free | yes |
| With inlay | no |
| Snap system | yes |
| Quick clip installation | Durchgangsloch, auf M6 Gewinde aufschraubbar |
| Clamping range D, max. | 37 mm |
| Clamping range D, min. | 31 mm |
| UV-resistant | no |