


# Technical data sheet

## Centre suspension for cable trays with rolled side rail FS

Item number: 6358500



Centre suspension for cable trays  
Maximum side height of the cable tray 60 mm. On filling, please ensure an even load distribution (no one-sided filling).

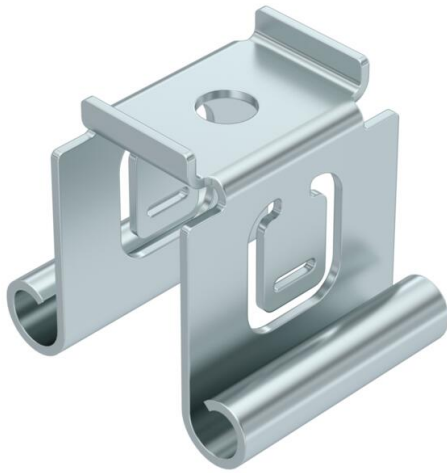

|           |                  |
|-----------|------------------|
| <b>St</b> | Steel            |
| <b>FS</b> | Strip galvanized |

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 6358500                 |
| Description 1                     | Centre suspension       |
| Description 2                     | for cable tray          |
| Manufacturer                      | OBO                     |
| Dimension                         | B50mm                   |
| Colour                            | zinc                    |
| Material                          | Steel                   |
| Surface                           | Strip galvanized        |
| Surface standard                  | DIN EN 10346            |
| Smallest sales unit               | 1                       |
| Unit of quantity                  | Piece                   |
| Weight                            | 5 kg                    |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,1471 kg COe / 1 Piece |


# Technical data sheet

## Centre suspension for cable trays with rolled side rail FS

Item number: 6358500



### Dimensions

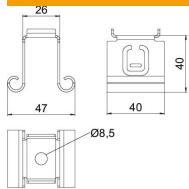

|              |         |
|--------------|---------|
| Length       | 40 mm   |
| Width        | 50 mm   |
| Height       | 39.5 mm |
| Dimension B  | 47 mm   |
| Dimension B1 | 26 mm   |

### Technical data

|                                  |           |
|----------------------------------|-----------|
| Version for                      | Suspended |
| Maintain electrical functions    | no        |
| for width max.                   | 50 mm     |
| for width min.                   | 50        |
| Suitable for metric threaded rod | 8         |
| Suitable for tray/ladder width   | 50 mm     |
| Hole diameter                    | 8.5 mm    |
| Adjustable                       | no        |