

Technical data sheet

2x BNC connection, 1 module, straight outlet, as 1:1 coupling, pure white
Item number: 6105090



Multimedia support with two BNC connection sockets, straight cable outlet, with labelling panel, two BNC couplings, socket-socket version. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data		
Item number	6105090	
Type	MTG-2BC F RW1	
Description 1	Multimedia support, audio BNC	
Description 2	2x coupling, socket-socket	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	2.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,092 kg CO2e / 1 Piece	


Technical data sheet

2x BNC connection, 1 module, straight outlet, as 1:1 coupling, pure white

Item number: 6105090



Dimensions

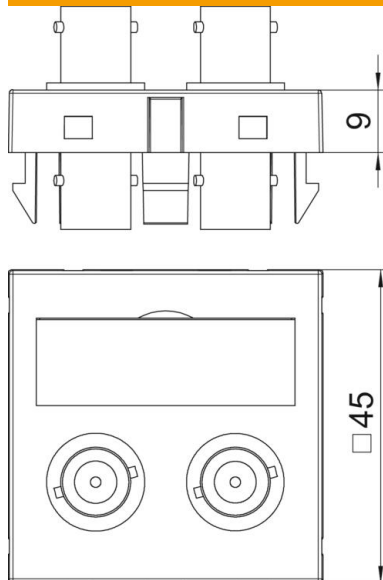

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	9 mm
Support ring	no
Transparent	no
Use	BNC/TNC
Strain relief option	no
Combination	Basic element with central cover plate