

Technical data sheet

DVI-I connection, 1 module, straight outlet, with connection cable

Item number: 6104754



Multimedia support with one DVI-I connection socket, straight cable outlet, with labelling panel, short DVI-I connection cable, socket-socket version. Support with locking fastening, suitable for horizontal and vertical installation in the system environment.



PC Polycarbonate

Master data

Item number	6104754
Type	MTG-DVI F RW1
Description 1	Multimedia support, DVI
Description 2	with cable, socket-socket
Manufacturer	OBO
Dimension	45x45mm
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,164 kg CO2e / 1 Piece


Technical data sheet

DVI-I connection, 1 module, straight outlet, with connection cable


Item number: 6104754



Dimensions

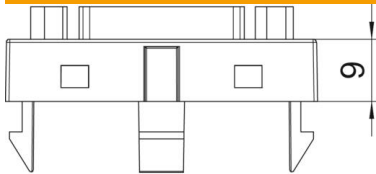

Width	45 mm
Height	45 mm

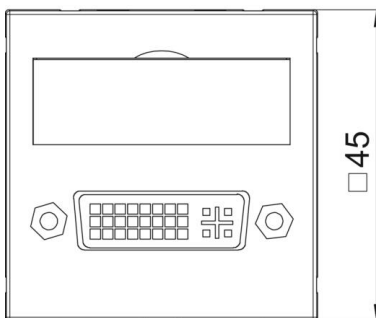

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Lighting	no
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	9 mm
Support ring	no
Transparent	no
Use	Miscellaneous
Strain relief option	no
Combination	Basic element with central cover plate
Outlet direction	Straight
With sockets/couplings	yes
Suitable for number of sockets/couplings	1