

Technical data sheet

DVI-D connection, 1 module, straight outlet, as screw connection

Item number: 6104730



Multimedia support with one DVI-D connection socket, straight cable outlet, with labelling panel, DVI-D socket with screw connection. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

Note: Due to the device dimensions, device installation in Rapid 45 device installation trunking is not possible.

PC Polycarbonate

Master data

Item number	6104730
Type	MTG-DVI S RW1
Description 1	Multimedia support, DVI
Description 2	socket with screw connection
Manufacturer	OBO
Dimension	45x45mm
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	3.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1172 kg CO2e / 1 Piece

Technical data sheet

DVI-D connection, 1 module, straight outlet, as screw connection


Item number: 6104730



Dimensions



Width	45 mm
Height	45 mm

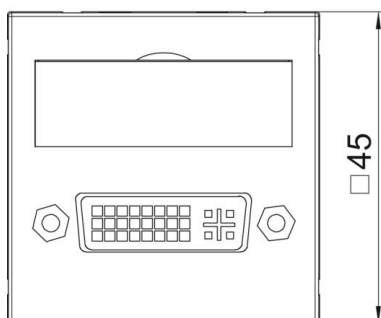

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	9 mm
Support ring	no
Transparent	no
Use	Miscellaneous
Strain relief option	no
Combination	Basic element with central cover plate