


Technical data sheet

Multimedia support for VGA/D-Sub9 plug connector, 1 module, slanting outlet

Item number: 6104718

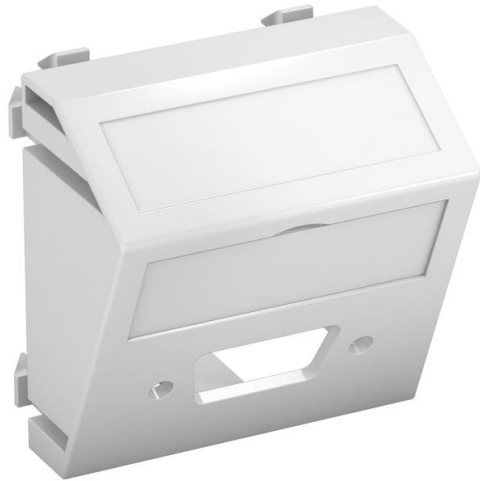

Multimedia support for a VGA/D-Sub9 plug connector, slanting cable outlet, with labelling panel, without plug connector. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data

Item number	6104718
Type	MTS-DB O RW1
Description 1	Multimedia support, VGA/D-Sub9
Description 2	without connection socket
Manufacturer	OBO
Dimension	45x45mm
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	0.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0929 kg CO2e / 1 Piece


Technical data sheet

Multimedia support for VGA/D-Sub9 plug connector, 1 module, slanting outlet

Item number: 6104718



Dimensions

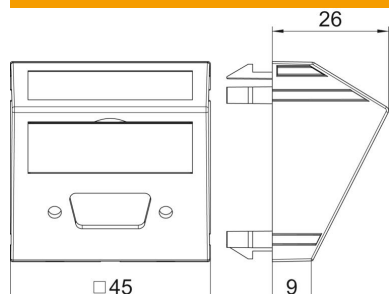

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	VGA
Strain relief option	no
Combination	Basic element with central cover plate