


Technical data sheet

VGA connection, 1 module, slanting outlet, with connection cable

Item number: 6104670



Multimedia support with one VGA connection socket, slanting cable outlet, with labelling panel, short VGA connection cable (HD15), socket-socket version. Support with locking fastening, suitable for horizontal and vertical installation in the system environment.

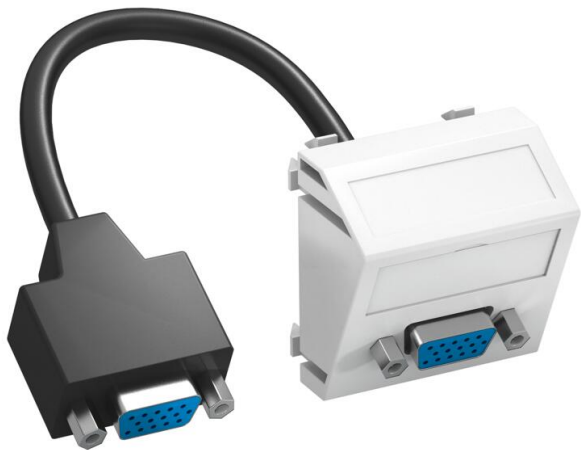

PC Polycarbonate

Master data		
Item number	6104670	
Type	MTS-VGA F RW1	
Description 1	Multimedia support, VGA	
Description 2	with cable, socket-socket	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	6.063 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1162 kg CO2e / 1 Piece	


Technical data sheet

VGA connection, 1 module, slanting outlet, with connection cable

Item number: 6104670



Dimensions

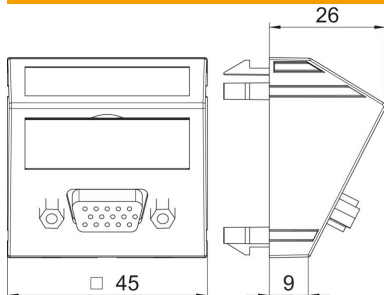

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	VGA
Strain relief option	no
Combination	Basic element with central cover plate