

# Technical data sheet

VGA connection, 1 module, slanting outlet, as screw connection

Item number: 6104628



Multimedia support with one VGA connection socket, slanting cable outlet, with labelling panel, VGA socket (HD15) with screw connection. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

## Master data

Item number	6104628
Type	MTS-VGA S AL 1
Description 1	Multimedia support, VGA
Description 2	socket with screw connection
Manufacturer	OBO
Dimension	45x45mm
Colour	Aluminium painted
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	2.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,08 kg CO2e / 1 Piece


# Technical data sheet

VGA connection, 1 module, slanting outlet, as screw connection

Item number: 6104628



## Dimensions

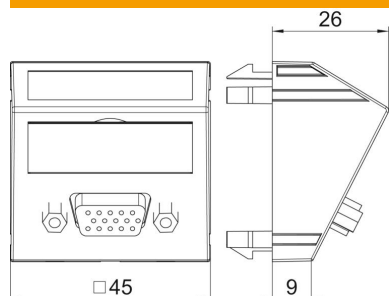

Width	45 mm
Height	45 mm

## Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	26 mm
Support ring	no
Transparent	no
Use	VGA
Strain relief option	no
Combination	Basic element with central cover plate