


Technical data sheet

Wall and support bracket MWA 12

Item number: 6424502



Light-duty wall and support bracket.

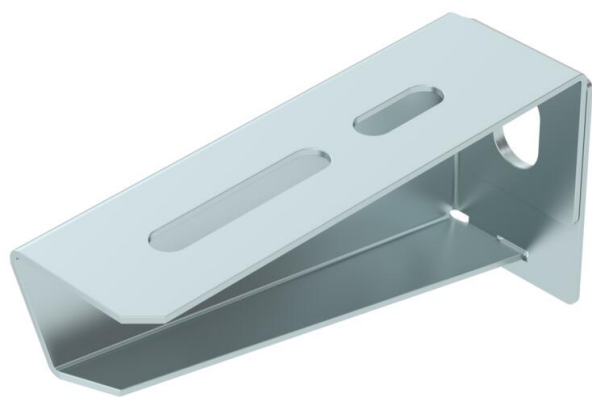

- St

Steel
- FS

Strip galvanized

| Master data         |                          |
|---------------------|--------------------------|
| Item number         | 6424502                  |
| Type                | MWA 12 11 FS RU          |
| Description 1       | Wall and support bracket |
| Description 2       | lightweight version      |
| Manufacturer        | OBO                      |
| Dimension           | B110mm                   |
| Material            | Steel                    |
| Surface             | Strip galvanized         |
| Surface standard    | DIN EN 10346             |
| Smallest sales unit | 1                        |
| Unit of quantity    | Piece                    |
| Weight              | 0 kg                     |
| Weight unit         | kg/100 pc.               |


# Technical data sheet

## Wall and support bracket MWA 12

Item number: 6424502



### Dimensions

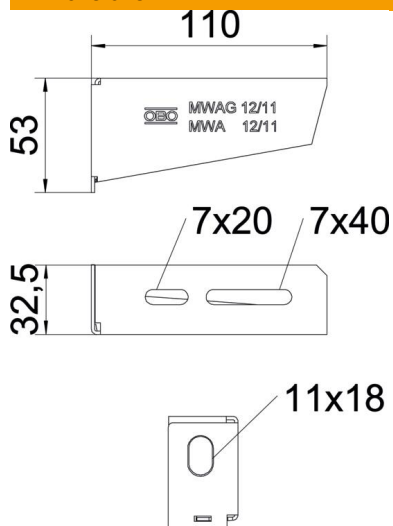

|             |         |
|-------------|---------|
| Length      | 32.5 mm |
| Width       | 110 mm  |
| Height      | 53 mm   |
| Dimension A | 32.5 mm |
| Dimension B | 110 mm  |
| Dimension H | 53 mm   |

### Technical data

|                               |                          |
|-------------------------------|--------------------------|
| Version for                   | Wall and support bracket |
| F in kN                       | 1.2 kN                   |
| Maintain electrical functions | no                       |
| Hole diameter                 | 11 mm                    |
| Rustproof steel, pickled      | no                       |
| Angle range, max.             | 90 mm                    |
| Angle range, min.             | 90 mm                    |