

# Technical data sheet

## Wall penetration

Item number: 7403890



Ready-to-mount trunking unit for passing through a wall, consisting of a trunking base with a blind lid. The scope of delivery contains a lid butt seal and a connector.



St	Steel
FS	Strip galvanized

### Master data

Item number	7403890
Type	OKB WD 25085
Description 1	Wall penetration
Description 2	with blanking lid
Manufacturer	OBO
Dimension	250x300x85
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	420 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	15,5351 kg CO2e / 1 Piece


# Technical data sheet

## Wall penetration

Item number: 7403890



### Dimensions

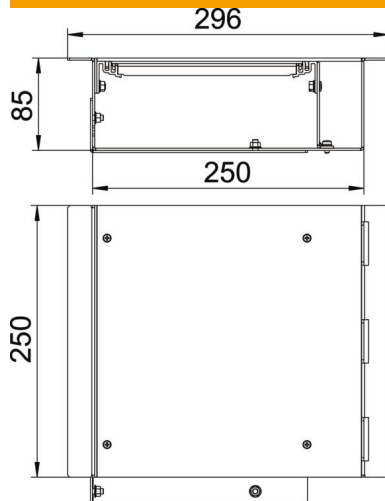

Length	300 mm
Width	250 mm
Height	93 mm
Dimension h	85 mm

### Technical data

Mounting opening cover	no
Type of accessory	Miscellaneous
Floor plate	yes
Floor care	Dry
Cover fastening, locking	no
Seal installation option	no
Decouplable	yes
Suitable for expansion joint	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for flushfloor, open underfloor trunking	yes
Suitable for screed-covered underfloor ducts	no
Minimum screed height	93
With connection opening	no
With equipotential bonding	no
With overhang	yes
Height-adjustment range, min.	0 mm
Removable cover	yes