

# Technical data sheet

**PYROPLUG® MagicBox, three-sided, interior height 110 mm**

Item number: 7204162



Fire protection box as insulation system, made of single-part stainless steel housing with intumescent fire protection inlays. Can be used in walls, on raw floors, beneath system floors and as insulation of rising sections in ceilings. Interior can be fully assigned with installations. For interior application. Closure of the residual openings with PYROSIT® NG fire protection foam, particularly simple for difficult geometries. CE-labelled construction product with general type approval. Fire resistance class EI90 (fire-resistant). Including graphite strip.



**A2** Stainless steel

**2B** Bright, treated

## Master data

Item number	7204162
Type	PMB 140-3 A2
Description 1	Fire Protection Box 3-sided
Description 2	with intumescent inlays
Available from	04.10.2022
Manufacturer	OBO
Dimension	300x423x166
Colour	stainless steel
Material	Stainless steel 1.4113
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	445.7 kg
Weight unit	kg/100 pc.


# Technical data sheet

PYROPLUG® MagicBox, three-sided, interior height 110 mm

Item number: 7204162



## Dimensions

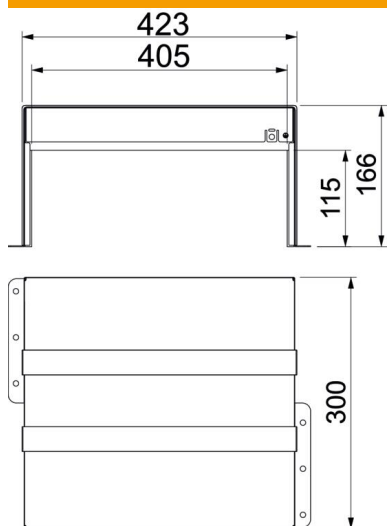

Length	300 mm
Width	423 mm
Height	166 mm
Dimension d	405 mm
Dimension d min.	423 mm

## Technical data

Fire protection version	Box body
Shape	Rectangular
Accessories required	yes
Internal height	115 mm
Internal width	405 mm