

# Technical data sheet

PYROPLUG® MagicBox, four-sided, interior height 110 mm

Item number: 7204140



Fire protection box as an insulation system, made of two-part stainless steel housing with intumescent fire protection inlays. Can be used in walls and ceilings. Quick mounting through the releasable Magic connection. Interior can be fully assigned with installations. For interior application. Closure of the residual openings with PYROSIT® NG fire protection foam, particularly simple for difficult geometries. CE-labelled construction product with general type approval. Fire resistance class EI90 (fire-resistant). Including graphite strip.



A2	Stainless steel
2B	Bright, treated

## Master data

Item number	7204140
Type	PMB 160-4 A2
Description 1	Fire Protection Box 4-sided
Description 2	with intumescent inlays
Available from	04.10.2022
Manufacturer	OBO
Dimension	300x623x181
Colour	stainless steel
Material	Stainless steel 1.4113
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	831.3 kg
Weight unit	kg/100 pc.


# Technical data sheet

PYROPLUG® MagicBox, four-sided, interior height 110 mm

Item number: 7204140



## Dimensions

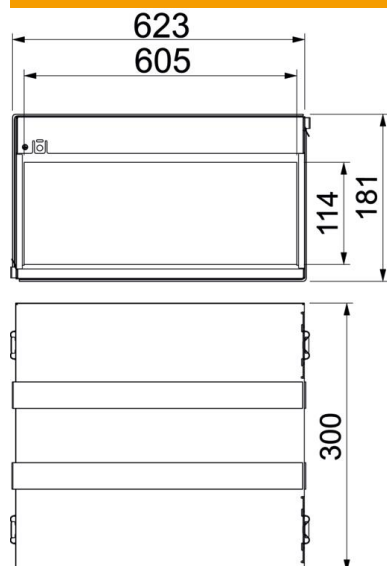

Length	300 mm
Width	623 mm
Height	181 mm
Dimension d	605 mm
Dimension d min.	623 mm

## Technical data

Fire protection version	Box body
Shape	Rectangular
Accessories required	yes
Internal height	114 mm
Internal width	605 mm