


# Technical data sheet

## Add-on tee 110 FT

Item number: 7123507

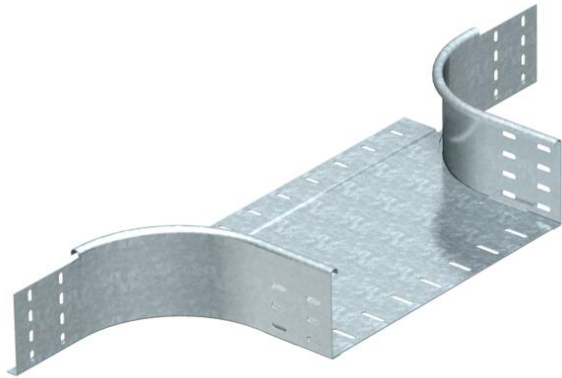

Add-on tee for horizontal and vertical use. For all cable tray types of 110 mm side height.  
Fastening materials should be ordered separately.




**St** Steel

**FT** Hot-dip galvanised

### Master data

Item number	7123507
Type	RAA 150 FT
Description 1	Add-on tee
Description 2	round version
Manufacturer	OBO
Dimension	110x500
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	310 kg
Weight unit	kg/100 pc.

### Dimensions

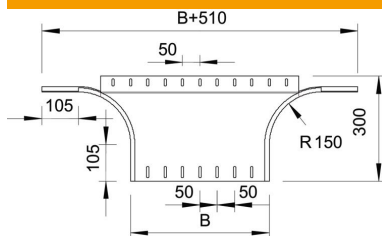

Width	500 mm
Width	20 in
Height	110 mm
Height	4 in
Dimension B	500 mm
Dimension R	150 mm

# Technical data sheet

Add-on tee 110 FT

Item number: 7123507



## Technical data

Bend (angle)	90°
Connector version	Without connectors
Maintain electrical functions	no
Material thickness, floor plate	1.5 mm
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	Screwed
Rail thickness	1.25 mm