

# Technical data sheet

## Add-on tee 35 FS

Item number: 6042103



Add-on tee for the creation of a horizontal branch or cross-over, fitting for lock and screw-on cable trays of side height 35 mm. Screw connection with FRS truss-head screws and M6 combination nuts. Can be used in indoor areas. Fastening material must be ordered separately.



St

Steel

FS

Strip galvanized

### Master data

|                                    |                          |
|------------------------------------|--------------------------|
| Item number                        | 6042103                  |
| Type                               | RAA 320 FS               |
| Description 1                      | Add-on tee               |
| Description 2                      | for cable tray           |
| Manufacturer                       | OBO                      |
| Dimension                          | 35x200                   |
| Colour                             | zinc                     |
| Material                           | Steel                    |
| Surface                            | Strip galvanized         |
| Surface standard                   | DIN EN 10346             |
| Smallest sales unit                | 1                        |
| Unit of quantity                   | Piece                    |
| Weight                             | 31.6 kg                  |
| Weight unit                        | kg/100 pc.               |
| CO2 Footprint (GWP) Cradle-to-Gate | 1,1252 kg CO2e / 1 Piece |


# Technical data sheet

## Add-on tee 35 FS

Item number: 6042103



### Dimensions

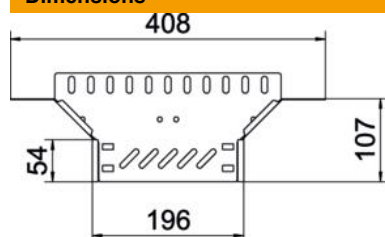

|                 |        |
|-----------------|--------|
| Width           | 200 mm |
| Height          | 35 mm  |
| Plate thickness | 0.8 mm |
| Dimension B     | 200 mm |
| Dimension R     | 50 mm  |

### Technical data

|                                         |                      |
|-----------------------------------------|----------------------|
| Departing width                         | 200 mm               |
| Connector version                       | Integrated connector |
| Maintain electrical functions           | no                   |
| Material thickness, floor plate         | 0.8 mm               |
| NATO hole pattern                       | no                   |
| Rustproof steel, pickled                | no                   |
| Permitted temperature range, max.       | 120 °C               |
| Permitted temperature range, min.       | -20 °C               |
| Wide-span version                       | no                   |
| Type of connector, cable support system | Screwed              |
| Recommended quantity of bolts           | 8 St.                |
| Rail thickness                          | 1.25 mm              |