

Technical data sheet

90° bend 60 FS

Item number: 6043098



90° bend, horizontal, for all cable tray types of 60 mm side height.
The fitting is shipped in an unmounted state.
Including appropriate fastening material.



St Steel

FS Strip galvanized

Master data

Item number	6043098
Type	RBL 90 640 FS RU
Description 1	90° bend
Description 2	horizontal
Manufacturer	OBO
Dimension	60x400
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	153 kg
Weight unit	kg/100 pc.


Technical data sheet

90° bend 60 FS

Item number: 6043098



Dimensions

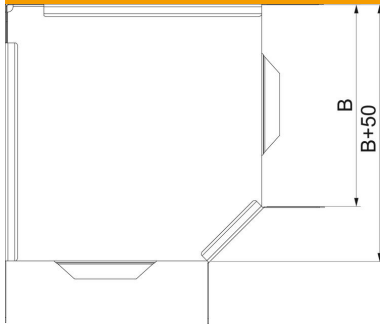

Width	400 mm
Height	60 mm
Plate thickness	0.7 mm
Dimension B	400 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Type	Bend, rigid
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed