


Technical data sheet

Magic bend, variable 85 FS

Item number: 6040580



Magic bend 0°–90°, variable, with quick connector system. For all cable tray types of 85 mm side height.

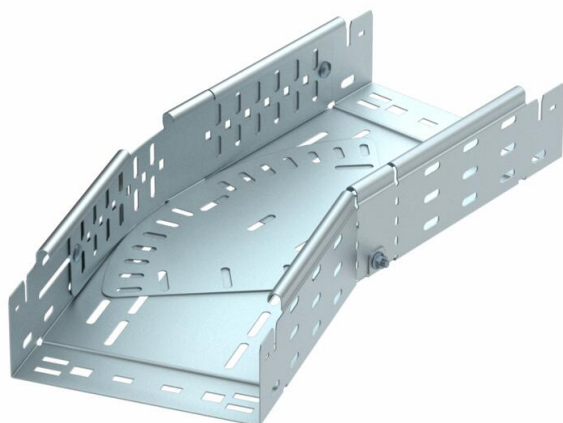

St Steel

FS Strip galvanized

Master data

Item number	6040580
Type	RBMV 810 FS
Description 1	Variable bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	85x100
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	88.5 kg
Weight unit	kg/100 pc.

Technical data sheet

Magic bend, variable 85 FS

Item number: 6040580



Dimensions



Width	100 mm
Height	85 mm
Plate thickness	1 mm
Dimension B	100 mm
Dimension L	340 mm

Technical data

Bend (angle)	Adjustable
Connector version	Integrated connector
Maintain electrical functions	no
Mounting perforation in base	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Type of connector, cable support system	Click fastening