


Technical data sheet

Magic bend, variable 85 FT

Item number: 6040606



Magic bend 0°–90°, variable, with quick connector system. For all cable tray types of 85 mm side height.

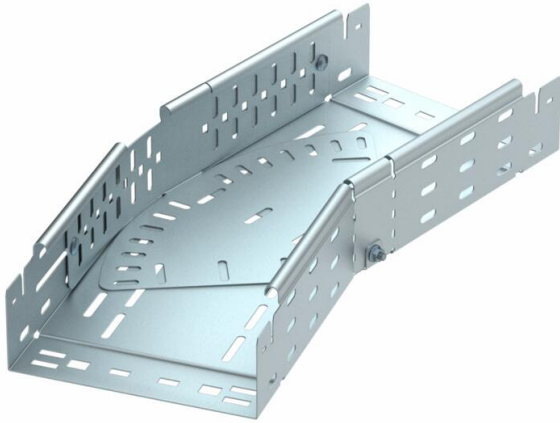

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6040606
Description 1	Variable bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	85x300
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	430.3 kg
Weight unit	kg/100 pc.

Technical data sheet

Magic bend, variable 85 FT

Item number: 6040606



Dimensions



Width	300 mm
Height	85 mm
Plate thickness	1.25 mm
Dimension B	300 mm
Dimension L	640 mm

Technical data

Bend (angle)	Adjustable
Connector version	Integrated connector
Maintain electrical functions	no
Mounting perforation in base	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Type of connector, cable support system	Click fastening