


# Technical data sheet

## Magic bend, variable 85 FS

Item number: 6040592



Magic bend 0°–90°, variable, with quick connector system. For all cable tray types of 85 mm side height.

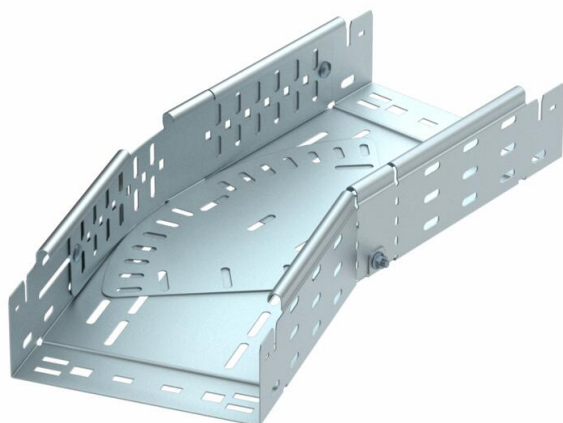

**St** Steel

**FS** Strip galvanized

### Master data

Item number	6040592
Type	RBMV 860 FS
Description 1	Variable bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	85x600
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1433.7 kg
Weight unit	kg/100 pc.

# Technical data sheet

Magic bend, variable 85 FS

Item number: 6040592



## Dimensions



Width	600 mm
Height	85 mm
Plate thickness	1.5 mm
Dimension B	600 mm
Dimension L	1,120 mm

## Technical data

Bend (angle)	Adjustable
Connector version	Integrated connector
Maintain electrical functions	no
Mounting perforation in base	yes
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Type of connector, cable support system	Click fastening