


Technical data sheet

45° Magic bend 60 FS

Item number: 6041040



45° bend with quick connector system. For all cable tray types of 60 mm side height.

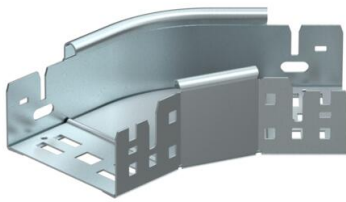

St	Steel
FS	Strip galvanized

Master data

Item number	6041040
Type	RBM 45 610 FS
Description 1	45° bend
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x100
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	50.4 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	1,6783 kg COe / 1 Piece


Technical data sheet

45° Magic bend 60 FS

Item number: 6041040



Dimensions

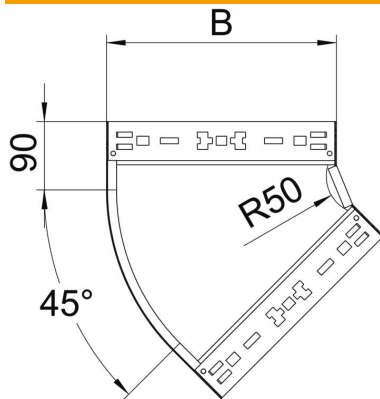

Width	100 mm
Width	4 in
Height	60 mm
Height	2 in
Plate thickness	1.25 mm
Dimension B	100 mm

Technical data

Bend (angle)	45°
Connector version	Integrated connector
Maintain electrical functions	yes
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Click fastening