


# Technical data sheet

## 90° Magic bend 60 A2

Item number: 6041184



90° bend with quick connector system. For all cable tray types of 60 mm side height.

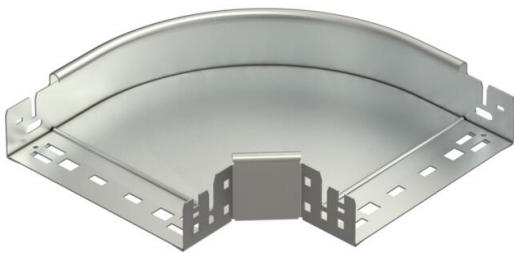

**A2** Stainless steel

**2B** Bright, treated

### Master data

|                     |                        |
|---------------------|------------------------|
| Item number         | 6041184                |
| Type                | RBM 90 620 A2          |
| Description 1       | 90° bend               |
| Description 2       | with quick connector   |
| Manufacturer        | OBO                    |
| Dimension           | 60x200                 |
| Material            | Stainless steel 1.4301 |
| Surface             | Bright, treated        |
| Surface standard    |                        |
| Smallest sales unit | 1                      |
| Unit of quantity    | Piece                  |
| Weight              | 121.9 kg               |
| Weight unit         | kg/100 pc.             |

# Technical data sheet

## 90° Magic bend 60 A2

Item number: 6041184



### Dimensions



|                 |         |
|-----------------|---------|
| Width           | 200 mm  |
| Height          | 60 mm   |
| Plate thickness | 1.25 mm |
| Dimension B     | 200 mm  |

### Technical data

|                                         |                      |
|-----------------------------------------|----------------------|
| Bend (angle)                            | 90°                  |
| Connector version                       | Integrated connector |
| Maintain electrical functions           | no                   |
| Mounting perforation in base            | no                   |
| NATO hole pattern                       | no                   |
| Change of direction                     | Horizontal           |
| Rustproof steel, pickled                | no                   |
| Side perforation                        | no                   |
| Wide-span version                       | no                   |
| Type of connector, cable support system | Click fastening      |