

Technical data sheet

90° bend 60 A4

Item number: 7134296



90° bend, horizontal and unperforated, for all cable tray types of 60 mm side height.
Fitting, unperforated, in round design. The interior radius of the fitting is 150 mm.
Fastening materials should be ordered separately.




| | |
|-----------|-----------------|
| A4 | Stainless steel |
| 2B | Bright, treated |

Master data

| | |
|---------------------|--------------------------|
| Item number | 7134296 |
| Description 1 | 90° bend |
| Description 2 | unperforated, round type |
| Manufacturer | OBO |
| Dimension | 60x600 |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 770 kg |
| Weight unit | kg/100 pc. |

Dimensions

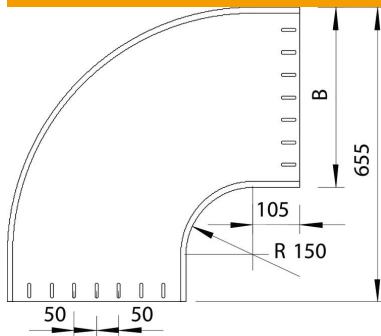

| | |
|-----------------|--------|
| Width | 600 mm |
| Width | 24 in |
| Height | 60 mm |
| Height | 2 in |
| Plate thickness | 1.5 mm |
| Dimension B | 600 mm |
| Dimension R | 150 mm |

Technical data

| | |
|---|--------------------|
| Bend (angle) | 90° |
| Connector version | Without connectors |
| Change of direction | Horizontal |
| Type of connector, cable support system | Screwed |