


Technical data sheet

45° bend 85 FT

Item number: 7067496

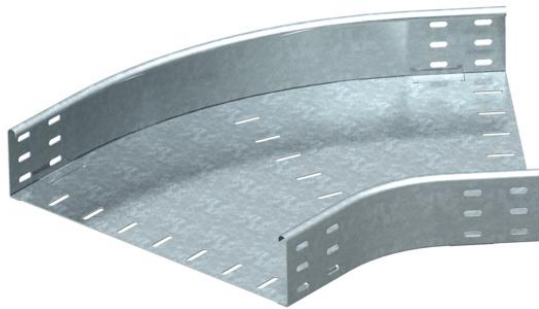

45° bend, horizontal, for all cable tray types of 85 mm side height.
Fastening materials should be ordered separately.



St

Steel


FT

Hot-dip galvanised

Master data

Item number	7067496
Description 1	45° bend
Description 2	horizontal, round type
Manufacturer	OBO
Dimension	85x500
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	439.7 kg
Weight unit	kg/100 pc.

Dimensions

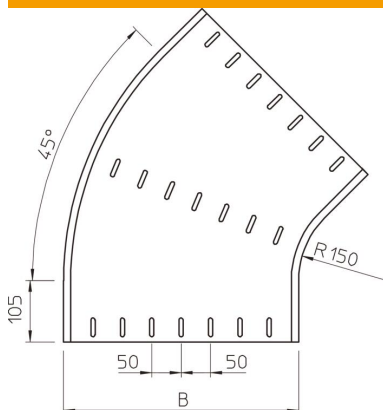

Width	500 mm
Width	20 in
Height	85 mm
Height	3 in
Dimension B	500 mm
Dimension R	150 mm

Technical data sheet

45° bend 85 FT

Item number: 7067496



Technical data

Bend (angle)	45°
Connector version	Without connectors
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed