


Technical data sheet

90° bend 60, black

Item number: 6043260



90° bend, horizontal, fitting for all cable tray types of 60 mm side height. Black coated.

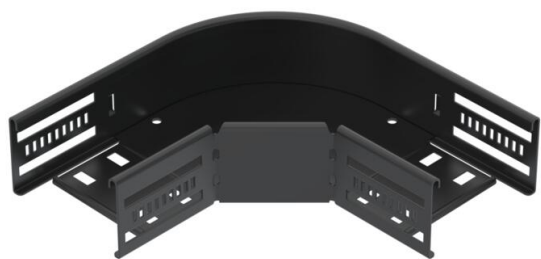

Steel



PES135 - Polyester

Master data		
Item number	6043260	
Type	RB 90 610 FSK SW	
Description 1	90° bend	
Description 2	for cable tray, horizontal	
Manufacturer	OBO	
Dimension	60x100	
Colour	Jet black; RAL 9005	
Material	Steel	
Surface	PES135 - Polyester	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	54 kg	
Weight unit	kg/100 pc.	


Technical data sheet

90° bend 60, black

Item number: 6043260



Dimensions

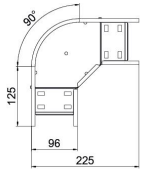

Width	100 mm
Height	60 mm
Dimension B	100 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Type	Bend, rigid
Material thickness, floor plate	0.8 mm
With cover	no
Mounting perforation in base	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Recommended quantity of bolts	10 St.
Rail thickness	1.25 mm