

Technical data sheet

90° bend 60 A4

Item number: 7134290



90° bend, horizontal, for all cable tray types of 60 mm side height.
The fitting is shipped in an unmounted state.
Including appropriate fastening material.
The 100 mm width has a rectangle shape and does not correspond to the image.



A4 Stainless steel

2B Bright, treated

Master data

| | |
|---------------------|------------------------------|
| Item number | 7134290 |
| Description 1 | 90° bend |
| Description 2 | horizontal + angle connector |
| Manufacturer | OBO |
| Dimension | 60x300 |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 166.6 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

90° bend 60 A4

Item number: 7134290



Dimensions

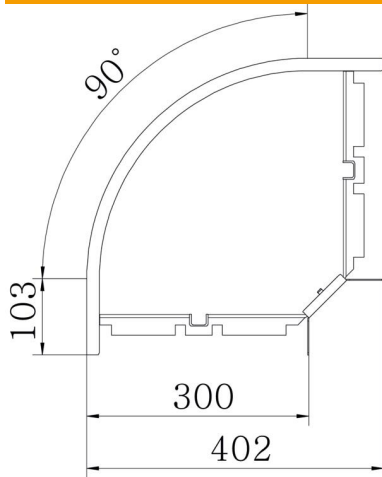

| | |
|-----------------|--------|
| Width | 300 mm |
| Width | 12 in |
| Height | 60 mm |
| Height | 2 in |
| Plate thickness | 1 mm |
| Dimension B | 300 mm |
| Dimension R | 50 mm |

Technical data

| | |
|---|---------------------|
| Bend (angle) | 90° |
| Connector version | Supplied connectors |
| Change of direction | Horizontal |
| Type of connector, cable support system | Screwed |