

Technical data sheet

90° bend 60 FS

Item number: 7001304



90° bend, horizontal, for all cable tray types of 60 mm side height.
Fitting in round design. The interior radius of the fitting is 150 mm. Fastening materials should be ordered separately.




St Steel

FS Strip galvanized

Master data

Item number	7001304
Type	RB 90 650 FS
Description 1	90° bend
Description 2	horizontal, round type
Manufacturer	OBO
Dimension	60x500
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	527 kg
Weight unit	kg/100 pc.

Dimensions

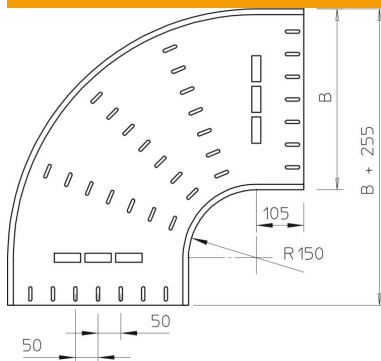

Width	500 mm
Width	20 in
Height	60 mm
Height	2 in
Plate thickness	1.5 mm
Dimension B	500 mm
Dimension R	150 mm

Technical data sheet

90° bend 60 FS

Item number: 7001304



Technical data

Bend (angle)	90°
Connector version	Without connectors
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed