

Technical data sheet

Adjustable bend element, vertical 110 FT

Item number: 7077106



Adjustable bend element, vertical, for all cable tray types with a side height of 110 mm.
RGV 110 adjustable connectors should be ordered separately and in the appropriate quantity.




St Steel

FT Hot-dip galvanised

Master data

Item number	7077106
Type	RGBEV 110 FT
Description 1	Adjustable bend element
Description 2	vertical
Manufacturer	OBO
Dimension	110x100
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	103.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,1549 kg CO2e / 1 Piece

Dimensions

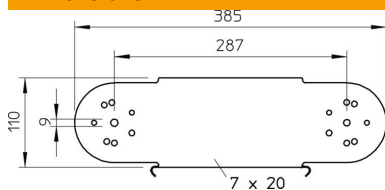

Width	100 mm
Width	4 in
Height	110 mm
Height	4 in
Plate thickness	1 mm
Dimension B	100 mm

Technical data sheet

Adjustable bend element, vertical 110 FT

Item number: 7077106



Technical data

Bend (angle)	Adjustable
Connector version	Without connectors
Type	Adjustable bend element
Maintain electrical functions	no
Mounting perforation in base	no
NATO hole pattern	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Side perforation	no
Wide-span version	no
Type of connector, cable support system	Screwed