


# Technical data sheet

## Magic cross-over 110 FT

Item number: 7027193



Cross-over with quick connector system. For all cable tray types of 110 mm side height.

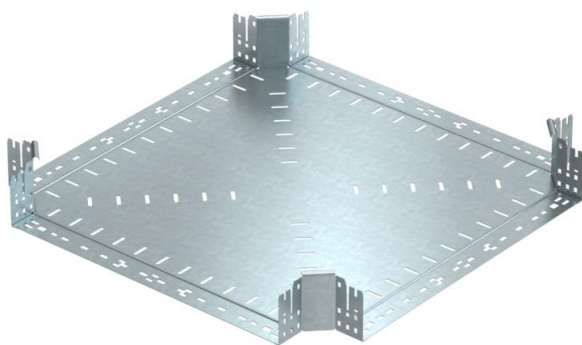

**St** Steel

**FT** Hot-dip galvanised

### Master data

Item number	7027193
Type	RKM 160 FT
Description 1	Cross over
Description 2	with quick connector
Manufacturer	OBO
Dimension	110x600
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	690.9 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Magic cross-over 110 FT

Item number: 7027193



### Dimensions

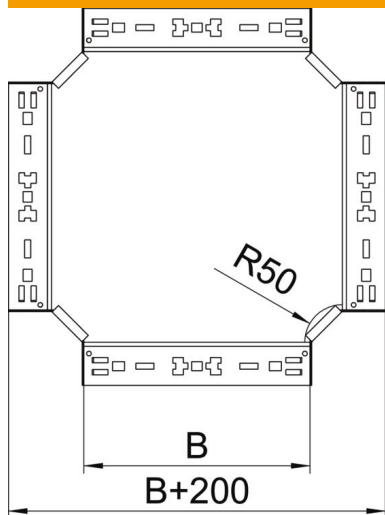

Width	600 mm
Height	110 mm
Plate thickness	1.25 mm
Dimension B	600 mm

### Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1.25 mm
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Click fastening
Rail thickness	1.25 mm