


# Technical data sheet

## Magic cross-over 60 FT

Item number: 7027029



Cross-over with quick connector system. For all cable tray types of 60 mm side height.

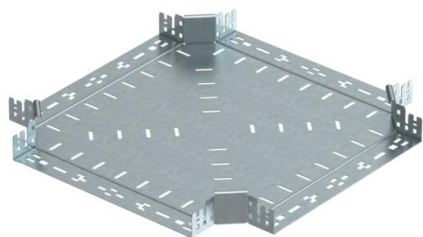

**St** Steel

**FT** Hot-dip galvanised

### Master data

Item number	7027029
Type	RKM 640 FT
Description 1	Cross over
Description 2	with quick connector
Manufacturer	OBO
Dimension	60x400
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	368.2 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Magic cross-over 60 FT

Item number: 7027029



### Dimensions

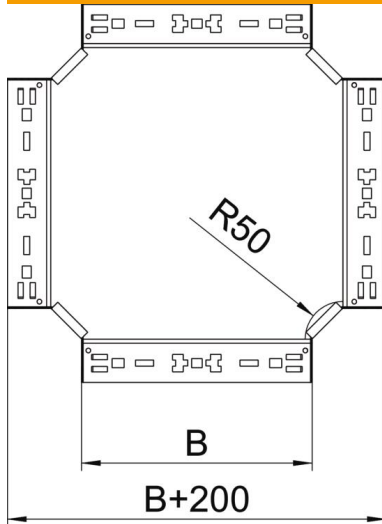

Width	400 mm
Width	16 in
Height	60 mm
Height	2 in
Plate thickness	1.25 mm
Dimension B	400 mm

### Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	yes
Material thickness, floor plate	1.25 mm
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Click fastening
Rail thickness	1.25 mm