

Technical data sheet

Magic cross-over 85 FT

Item number: 7027101



Cross-over with quick connector system. For all cable tray types of 85 mm side height.



St Steel

FT Hot-dip galvanised

Master data


Item number	7027101
Type	RKM 810 FT
Description 1	Cross over
Description 2	with quick connector
Manufacturer	OBO
Dimension	85x100
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	116.6 kg
Weight unit	kg/100 pc.

Technical data sheet

Magic cross-over 85 FT

Item number: 7027101

Dimensions

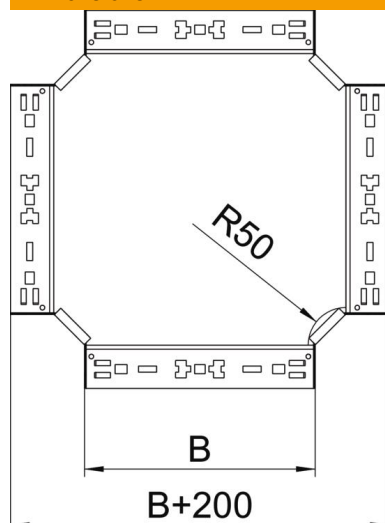

Width	100 mm
Height	85 mm
Plate thickness	1.25 mm
Dimension B	100 mm

Technical data

Bend (angle)	90°
Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1.25 mm
NATO hole pattern	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Click fastening
Rail thickness	1.25 mm