

Technical data sheet

Height-adjustable cassette for inspection opening, RKN, brass

Item number: 7409002



Height-adjustable "blank" cassette for the creation of an inspection opening of nominal size 4 in dry or wet-care floors for indoor use. Only suitable for smooth floor coverings.

For the installation of 2 UT3 universal supports for 4 individual installation devices with support ring/support clamp or 6 Modul 45 devices.



CuZn
37 Brass

Master data

Item number	7409002
Description 1	Square cassette
Description 2	blank
Manufacturer	OBO
Dimension	200x200mm
Material	Brass
Smallest sales unit	1
Unit of quantity	Piece
Weight	321.6 kg
Weight unit	kg/100 pc.


Technical data sheet

Height-adjustable cassette for inspection opening, RKN, brass

Item number: 7409002



Dimensions

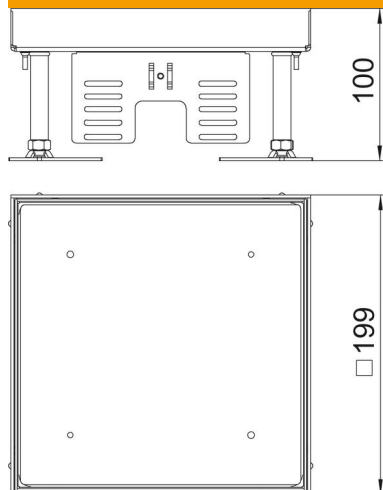

Length	199 mm
Width	199 mm
Dimension h	100 mm

Technical data

Number of installable devices	0
Number of mounting boxes	2
Number of cable outlets	0
Version for	Square
Cable outlet version	No cable outlet
Floor care	Wet
Decouplable	no
Floor height, max.	150 mm
Floor height, min.	100 mm
Suitable for raised floor installation	yes
Suitable for cavity floor installation	yes
Suitable for underfloor box	250/350
Device support to accept mounting boxes	no
Length of installation dimensions	201 mm
Nominal size for device installation units	4
Height-adjustment range, max.	150 mm
Height-adjustment range, min.	100 mm
Protection rating (IP) when used	IP00
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Heavy-duty version	no
Installation system type	UT3
Vertical load, large area	to 15,000 N
Vertical load, small area	to 3,000 N
Approvals	VDE
Floor covering thickness	20 mm