

Technical data sheet

Height-adjustable cassette for inspection opening, RKN,
stainless steel

Item number: 7409044



Height-adjustable "blank" cassette for the creation of an inspection opening of nominal size 9 in dry or wet-cleaned floors for indoor use. Only suitable for smooth floor coverings.
For the installation of 3 UT4 universal supports for 9 individual installation devices with support ring/support clamp or 12 Modul 45 devices.



A2 Stainless steel

Master data

Item number	7409044
Description 1	Square cassette
Description 2	blank
Manufacturer	OBO
Dimension	243x243mm
Material	Stainless steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	440 kg
Weight unit	kg/100 pc.

Technical data sheet

Height-adjustable cassette for inspection opening, RKN,
stainless steel


Item number: 7409044



Dimensions



Length	243 mm
Width	243 mm
Dimension h	100 mm

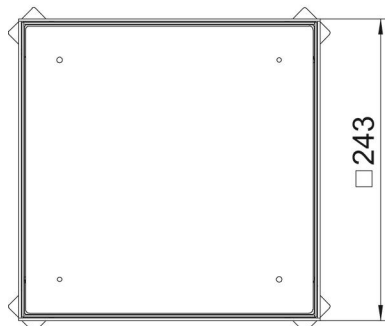

Technical data

Number of installable devices	0
Number of mounting boxes	3
Number of cable outlets	0
Version for	Square
Cable outlet version	No cable outlet
Floor care	Wet
Decouplable	no
Floor height, max.	150 mm
Floor height, min.	100 mm
Suitable for raised floor installation	yes
Suitable for cavity floor installation	yes
Suitable for underfloor box	250/350
Device support to accept mounting boxes	no
Length of installation dimensions	244 mm
Nominal size	350 mm
Nominal size for device installation units	9
Height-adjustment range, max.	150 mm
Height-adjustment range, min.	100 mm
Protection rating (IP) when used	IP00
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Heavy-duty version	no
Installation system type	UT4
Vertical load, large area	to 15,000 N
Vertical load, small area	to 3,000 N
Approvals	VDE
Floor covering thickness	20 mm