

Technical data sheet

Height-adjustable cassette for inspection opening, RKN,
stainless steel

Item number: 7409046



Height-adjustable "blank" cassette for the creation of an inspection opening of nominal size 9 in dry or wet-cleaned floors for indoor use. Only suitable for smooth floor coverings.
For the installation of 3 UT4 universal supports for 9 individual installation devices with support ring/support clamp or 12 Modul 45 devices.



A2 Stainless steel

Master data

| | |
|---------------------|-----------------|
| Item number | 7409046 |
| Description 1 | Square cassette |
| Description 2 | blank |
| Manufacturer | OBO |
| Dimension | 243x243mm |
| Material | Stainless steel |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 451 kg |
| Weight unit | kg/100 pc. |

Technical data sheet

Height-adjustable cassette for inspection opening, RKN,
stainless steel


Item number: 7409046



Dimensions



| | |
|-------------|--------|
| Length | 243 mm |
| Width | 243 mm |
| Dimension h | 105 mm |

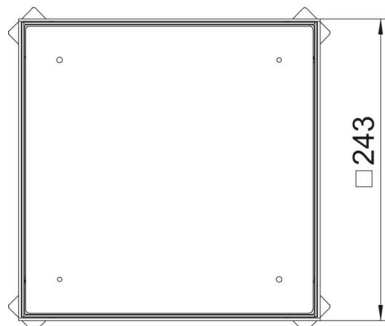

Technical data

| | |
|--|-----------------|
| Number of installable devices | 0 |
| Number of mounting boxes | 3 |
| Number of cable outlets | 0 |
| Version for | Square |
| Cable outlet version | No cable outlet |
| Floor care | Wet |
| Decouplable | no |
| Floor height, max. | 155 mm |
| Floor height, min. | 105 mm |
| Suitable for raised floor installation | yes |
| Suitable for cavity floor installation | yes |
| Suitable for underfloor box | 250/350 |
| Device support to accept mounting boxes | no |
| Length of installation dimensions | 244 mm |
| Nominal size | 350 mm |
| Nominal size for device installation units | 9 |
| Height-adjustment range, max. | 155 mm |
| Height-adjustment range, min. | 105 mm |
| Protection rating (IP) when used | IP00 |
| Protection rating (IP) when unused | IP40 |
| Protection rating IK code | IK10 |
| Heavy-duty version | no |
| Installation system type | UT4 |
| Vertical load, large area | to 15,000 N |
| Vertical load, small area | to 3,000 N |
| Approvals | VDE |
| Floor covering thickness | 25 mm |