

Technical data sheet

Height-adjustable cassette for inspection opening,
RKNUZD3, stainless steel
Item number: 7409060



Height-adjustable "blank" cassette, decoupled from the floor, for the creation of an inspection opening of nominal size 4 in dry or wet-cleaned floors for indoor use, for mounting in underfloor boxes UZD250 or UZD350, either in conjunction with a blanking lid DUG./4 or in UGD250-3/4 or UGD350-3/4. Mounting takes place using levelling profiles (order separately) in the aluminium frame profile of the underfloor boxes. Only suitable for smooth floor coverings. Height-adjustable cassette as a blind cassette, two-compartment 2. APMT2 cover plates can be installed. For the installation of 2 UT3 universal supports for 4 individual installation devices with support ring/support clamp or 6 Modul 45 devices.



A2 Stainless steel

Master data


| | |
|------------------------------------|---------------------------|
| Item number | 7409060 |
| Type | RKN2 UZD3 4VS25 |
| Description 1 | Square cassette |
| Description 2 | blank |
| Manufacturer | OBO |
| Dimension | 200x200mm |
| Material | Stainless steel 1.4301 |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 222 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 13,7261 kg CO2e / 1 Piece |

Technical data sheet

Height-adjustable cassette for inspection opening,
RKNUZD3, stainless steel
Item number: 7409060



Dimensions

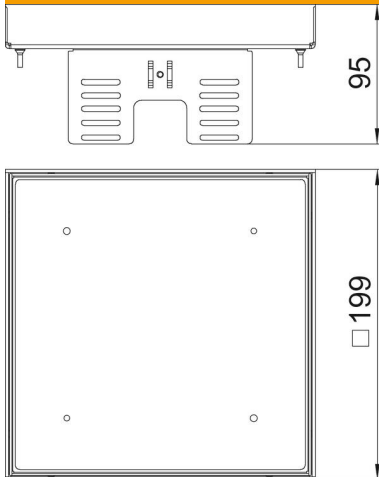

| | |
|-------------|--------|
| Length | 199 mm |
| Width | 199 mm |
| Height | 95 mm |
| Dimension h | 95 mm |

Technical data

| | |
|--|-----------------|
| Number of installable devices | 0 |
| Number of cable outlets | 0 |
| Version for | Square |
| Cable outlet version | No cable outlet |
| Floor care | Wet |
| Decouplable | yes |
| Floor height, min. | 110 mm |
| Suitable for raised floor installation | yes |
| Suitable for cavity floor installation | yes |
| Suitable for underfloor box | 250/350 |
| Device support to accept mounting boxes | no |
| Length of installation dimensions | 201 mm |
| Nominal size for device installation units | 4 |
| Protection rating (IP) when used | IP00 |
| Protection rating (IP) when unused | IP44 |
| Protection rating IK code | IK10 |
| Heavy-duty version | no |
| Installation system type | UT3 |
| Vertical load, large area | to 3,000 N |
| Vertical load, small area | to 3,000 N |
| Approvals | VDE |
| Floor covering thickness | 25 mm |