


# Technical data sheet

RKSN2 4 with UT3 45

Item number: 7429618

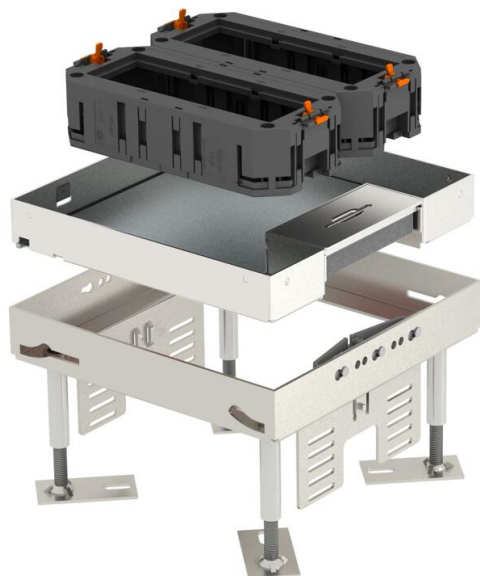

Height-adjustable cassette with all necessary system accessories for direct installation in all floor types with dry-care floor coverings for indoor use.

The scope of delivery contains:

- Cassette of nominal size 9 with cord outlet,
- Two UT3/45 universal supports, each for four Modul 45® devices. Stainless cassette and cord outlet. 25 mm floor covering recess in the cassette.



A2 Stainless steel

## Master data

Item number	7429618
Type	RKSN2 4 KU V25
Description 1	Cassette construction set
Description 2	for all floors
Manufacturer	OBO
Material	Stainless steel 1.4301
Smallest sales unit	1
Unit of quantity	Piece
Weight	338 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	16,6918 kg CO2e / 1 Piece


# Technical data sheet

RKSN2 4 with UT3 45

Item number: 7429618



## Dimensions

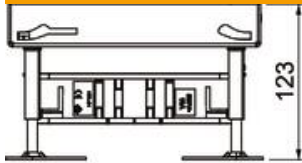

## Technical data

Cable outlet version	Swivellable cord outlet
Floor height, max.	155 mm
Floor height, min.	110 mm
Height-adjustment range, max.	155 mm
Height-adjustment range, min.	110 mm
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK10
Floor covering thickness	25 mm