


Technical data sheet

Height-adjustable cassette with cord outlet, RKSNUZD3, brass

Item number: 7409222

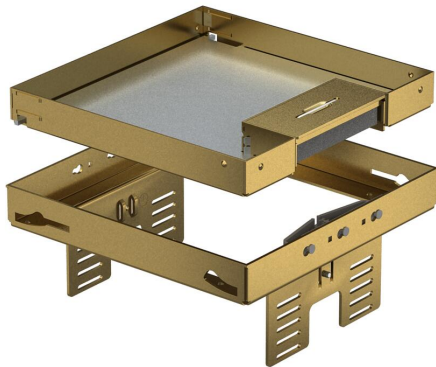

Height-adjustable cassette, decoupled from the floor, of nominal size 4, with cord outlet, for the installation of accessories in dry-cleaned floors indoors, for mounting in underfloor boxes UZD250 or UZD350, either in conjunction with a mounting cover DUG../4 or in UGD250-3/4 or UGD350-3/4. Mounting takes place using height-adjustment brackets (order separately) in the aluminium frame profile of the underfloor boxes.

Height-adjustable cassette for cord outlet, 2-compartment. 2 APMT2 cover plates can be installed. For the installation of 2 UT3 universal supports for 4 individual installation devices with support ring/support clamp or 6 Modul 45 devices.



Master data

| | |
|------------------------------------|---------------------------|
| Item number | 7409222 |
| Type | RKSN2 UZD3 4MS20 |
| Description 1 | Square cassette |
| Description 2 | with cord outlet |
| Manufacturer | OBO |
| Dimension | 200x200mm |
| Material | Brass |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 224 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 10,1851 kg CO2e / 1 Piece |


Technical data sheet

Height-adjustable cassette with cord outlet, RKSNUZD3, brass

Item number: 7409222



Dimensions

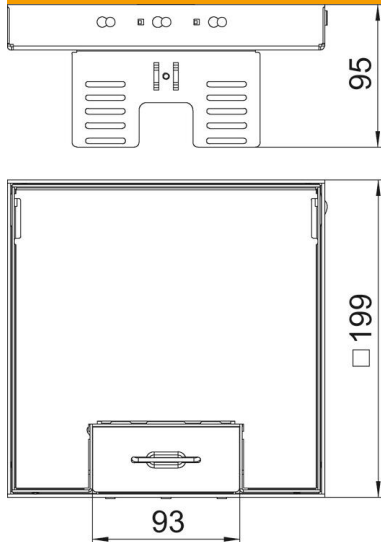

Dimension h 90 mm

Technical data

| | |
|--|-------------------------|
| Number of installable devices | 6 |
| Number of mounting boxes | 2 |
| Number of cable outlets | 1 |
| Version for | Square |
| Cable outlet version | Swivellable cord outlet |
| Floor care | Dry |
| Decouplable | yes |
| Floor height, min. | 105 mm |
| Suitable for raised floor installation | yes |
| Suitable for cavity floor installation | yes |
| Suitable for underfloor box | 250/350 |
| Device support to accept mounting boxes | yes |
| Nominal size for device installation units | 4 |
| Standard | EN 50085-2-2 |
| Protection rating (IP) when used | IP20 |
| Protection rating (IP) when unused | IP40 |
| Protection rating IK code | IK10 |
| Heavy-duty version | no |
| Installation system type | UT3 |
| Vertical load, large area | to 3,000 N |
| Vertical load, small area | to 3,000 N |
| Approvals | VDE |
| Floor covering thickness | 20 mm |