


Technical data sheet

Cross-over 60 A2

Item number: 7027509



Cross-over for the creation of a horizontal branch, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nut. Can be used indoors and outdoors. Fastening material must be ordered separately.

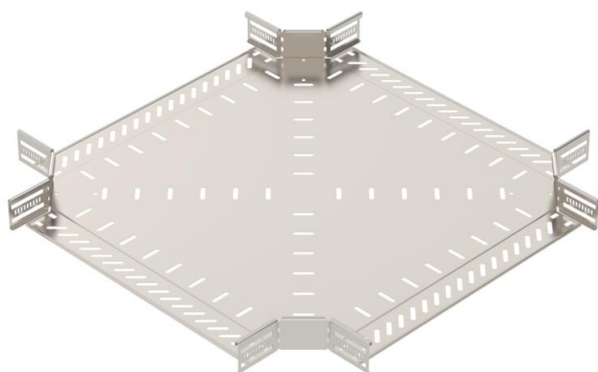

A2 Stainless steel

2B Bright, treated

Master data

| | |
|---------------------|-----------------|
| Item number | 7027509 |
| Description 1 | Cross over |
| Description 2 | for cable tray |
| Manufacturer | OBO |
| Dimension | 60x500 |
| Colour | stainless steel |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 404.5 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

Cross-over 60 A2

Item number: 7027509



Dimensions

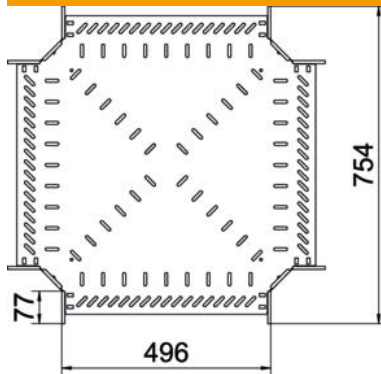

| | |
|-----------------|--------|
| Width | 500 mm |
| Height | 60 mm |
| Plate thickness | 1 mm |
| Dimension B | 500 mm |

Technical data

| | |
|---|----------------------|
| Connector version | Integrated connector |
| Maintain electrical functions | no |
| Material thickness, floor plate | 1 mm |
| NATO hole pattern | no |
| Rustproof steel, pickled | no |
| Permitted temperature range, max. | 120 °C |
| Permitted temperature range, min. | -20 °C |
| Wide-span version | no |
| Type of connector, cable support system | screwed/clamped |
| Recommended quantity of bolts | 32 St. |
| Rail thickness | 1.25 mm |