


Technical data sheet

Cross-over 60 A2

Item number: 7027511



Cross-over for the creation of a horizontal branch, fitting for lock and screw-on cable trays of side height 60 mm. Screwless mounting with double clamps or screw connection with FRS truss-head screws and M6 combination nuts. Can be used indoors and outdoors. Fastening material must be ordered separately.

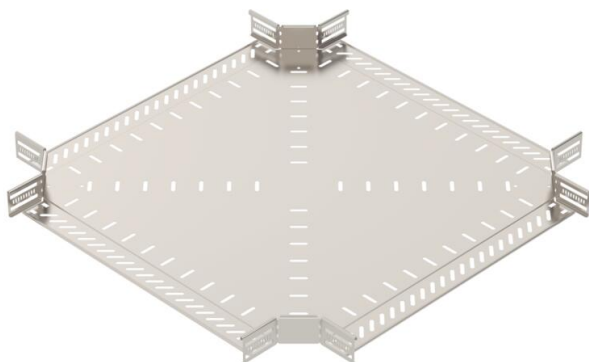

A2 Stainless steel

2B Bright, treated

Master data

Item number	7027511
Description 1	Cross over
Description 2	for cable tray
Manufacturer	OBO
Dimension	60x600
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	521.8 kg
Weight unit	kg/100 pc.


Technical data sheet

Cross-over 60 A2

Item number: 7027511



Dimensions

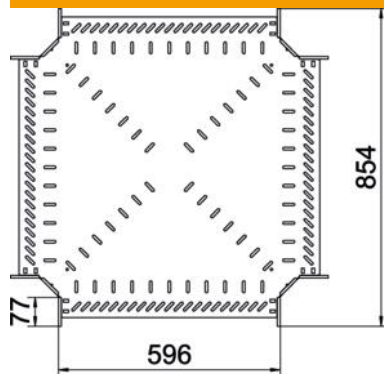

Width	600 mm
Height	60 mm
Plate thickness	1 mm
Dimension B	600 mm

Technical data

Connector version	Integrated connector
Maintain electrical functions	no
Material thickness, floor plate	1 mm
NATO hole pattern	no
Rustproof steel, pickled	no
Permitted temperature range, max.	120 °C
Permitted temperature range, min.	-20 °C
Wide-span version	no
Type of connector, cable support system	screwed/clamped
Recommended quantity of bolts	32 St.
Rail thickness	1.25 mm