


# Technical data sheet

## 60 FS cross-over

Item number: 7004435



Horizontal cross-over for all cable tray types of 60 mm side height.  
Fitting in round design. The interior radius of the fitting is 150 mm. All the sides are designed for the same cable tray width.  
Fastening materials should be ordered separately.

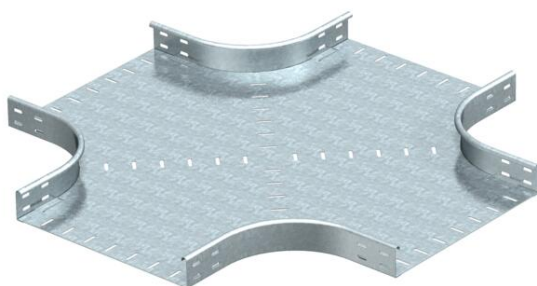

**St** Steel

**FS** Strip galvanized

### Master data

Item number	7004435
Type	RK 660 FS
Description 1	Cross over
Description 2	horizontal, round type
Manufacturer	OBO
Dimension	60x600
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1291 kg
Weight unit	kg/100 pc.


# Technical data sheet

60 FS cross-over

Item number: 7004435



## Dimensions

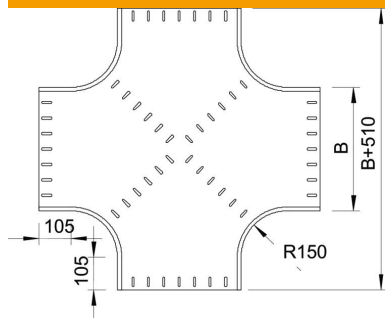

Width	600 mm
Width	24 in
Height	60 mm
Height	2 in
Plate thickness	1.5 mm
Dimension B	600 mm
Dimension R	150 mm

## Technical data

Bend (angle)	90°
Maintain electrical functions	no
Material thickness, floor plate	1.5 mm
Change of direction	Horizontal
Rustproof steel, pickled	no
Wide-span version	no
Type of connector, cable support system	Screwed
Rail thickness	1.25 mm